


On-load tap-changer type UBBD, 27 tap positions, coarse/fine-switching.
 Min effective No. of turns in pos 1.
 The tap-changer is delivered set in pos 14, the preceding pos. was 13.

Lindningskopplare typ UBBD, 27 lägen, grov/fin-koppling.
 Min antal effektiva varv i läge 1.
 Lindningskopplaren levereras inställd i läge 14, föregående läge var 13.

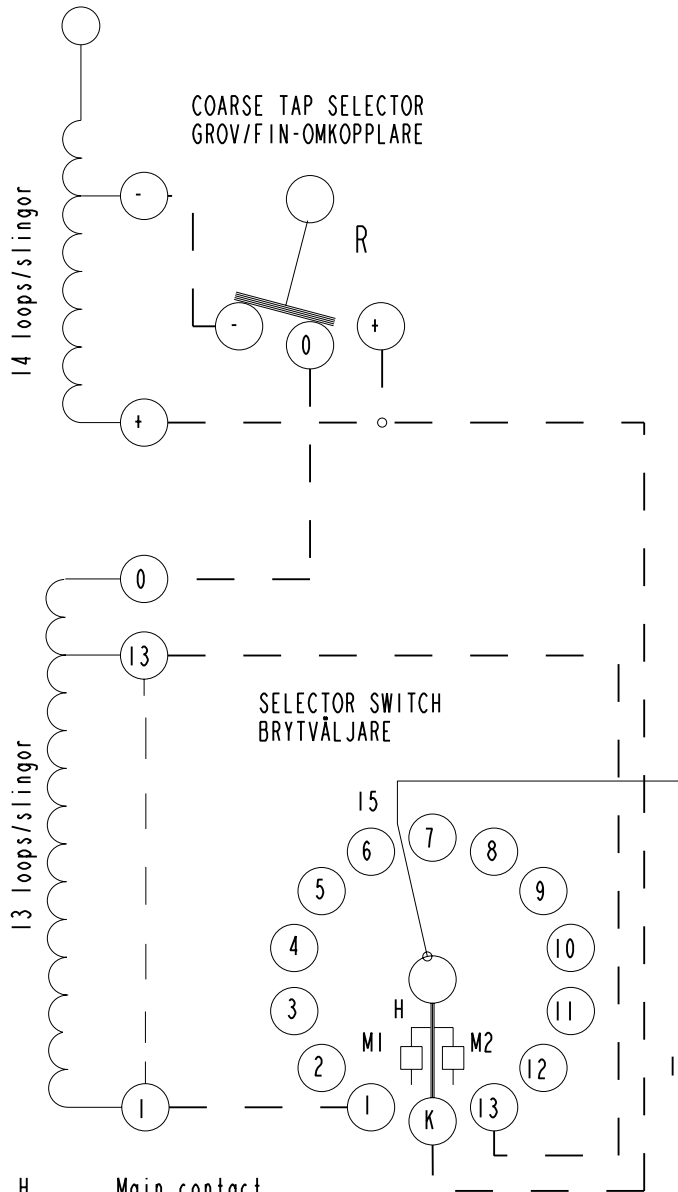

H Main contact
 Huvudkontakt
 M1, M2 Transition contacts
 Motståndskontakter

Pos Läge	R connects förbinder	H connects förbinder
1		13 - 15
2		12 - 15
3		11 - 15
4		10 - 15
5		9 - 15
6		8 - 15
7	0 -	7 - 15
8		6 - 15
9		5 - 15
10		4 - 15
11		3 - 15
12		2 - 15
13		1 - 15
14		K - 15
15		13 - 15
16		12 - 15
17		11 - 15
18	0+	10 - 15
19		9 - 15
20		8 - 15
21		7 - 15
22		6 - 15
23		5 - 15
24		4 - 15
25		3 - 15
26		2 - 15
27		1 - 15

1) OUTPUT TERMINAL
 STRÖMAVTAGNING

1) Internal connections between the terminals 15 of the three phases are included in the star-point type. Dashed lines show in delivery not included leads belonging to cleats and leads.

Inre förbindningar mellan uttag 15 i de tre faserna ingår i nollpunktsutförande. Streckade linjer visar i leveransen ej ingående ledare tillhörande anslutningsdonet.

Sheet	Cont	Year	Week	Dept	Rev Ind	Revision	Appd	Year	Week	
Accepted by	qual control		Accepted for prod by		Description (English)					
R. Yngvesson					CONNECTION DIAGRAM UBBD					
Design checked by	B-O. Stenestam		Drawn by		Description (own language)					
M. Hedlund			L. Bergman		KOPPLINGSSCHEMA UBBD					
Drawing checked by	M. Hedlund		Issued by		Dept		Year	Week		
			COM/TKO		97		32			
					Asea Brown Boveri					
5492 0392-11					DATA ORIGINAL					
					Lang		Sheet			
							1			
					Rev Ind		Cont			

We reserve all rights in this document and in the information contained therein. Reproduction, use or disclosure to third parties without express authority is strictly forbidden. © ABB 19