



GoFa™ 10 and GoFa™ 12

Higher payloads

Payloads of up to 10 and 12 kilos

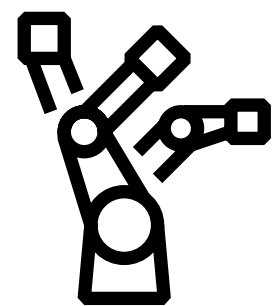

14% longer reach than other comparable robots in market

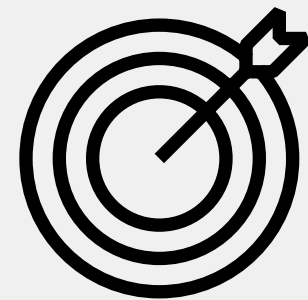


Best repeatability of **0.02 mm** on the market

2 m/s

Easy to use and Tool Center Point speed of 2 m/s

Longer reach

Longer reach of up to 1.62 meters

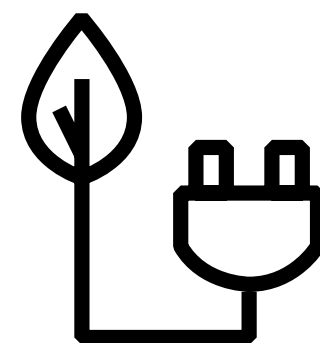

Up to **20%** energy savings with OmniCore™

